


# ボルト径基準による 6 画 2 面幅寸法表

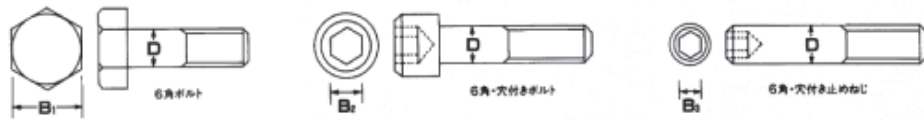

## ■メートルネジ

ボルト径	六角 ボルト・ナット	小型・六角 ボルト・ナット	高力・六角 ボルト・ナット	六角・穴付き ボルト	六角・穴付き 止めねじ
Dmm	B <sub>1</sub> mm	B <sub>1</sub> mm	B <sub>1</sub> mm	B <sub>2</sub> mm	B <sub>3</sub> mm
M2	4				
M2.2	4.5				
M2.5	5				
M3	5.5			2.5	1.5
M3.5	6				
M4	7			3	2
M4.5	8				
M5	8			4	2.5
M6	10			5	3
M7	11				
M8	13	12		6	4
M10	16	14		8	5
M12	18	17	22	10	6
M14	21	19		12	
M16	24	22	27	14	8
M18	27	24		14	
M20	30	27	32	17	10
M22	32	30	36	17	
M24	36	32	41	19	
M27	41	36	46	19	
M30	46	41	50	22	
M33	50	46		24	
M36	55	50		27	
M39	60	55		27	
M42	65			32	
M45	70			32	
M48	75			36	
M52	80			36	
M56	85				
M60	90				
M64	95				
M68	100				
M72	105				
M76	110				
M80	115				
M85	120				

## ■ウィットネジ

ボルト径	六角・穴付き 止めねじ
Dinch	B <sub>3</sub> mm
W 3/8	17
W 7/16	19
W 1/2	21
W 5/8	26
W 3/4	32
W 7/8	35
W1	41
W1 1/8	46
W1 1/4	50
W1 3/8	54
W1 1/2	58
W1 5/8	63
W1 3/4	67
W1 7/8	71
W2	77
W2 1/4	85
W2 1/2	95
W2 3/4	105
W3	110
W3 1/4	120